


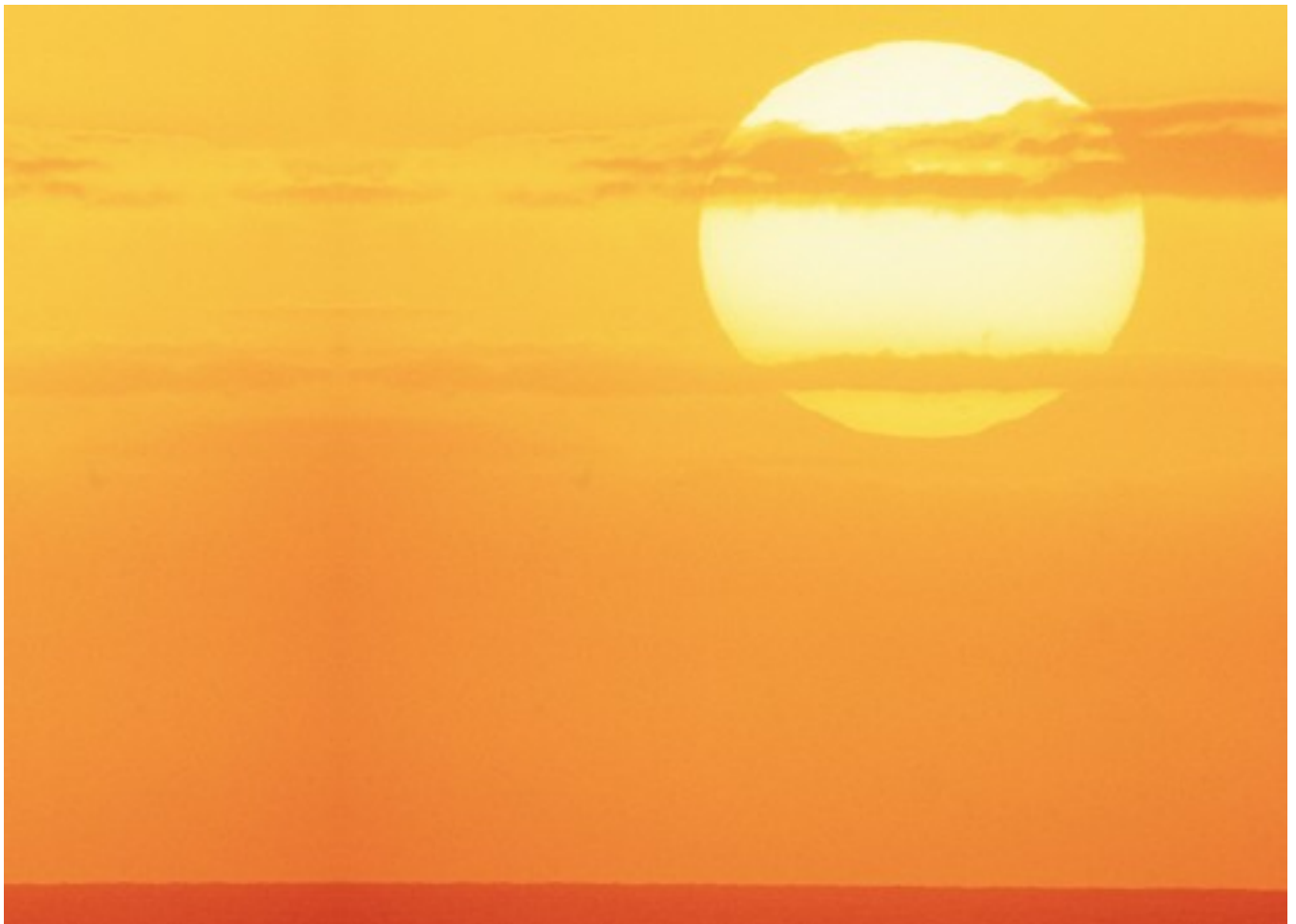

Cool Products For Hot Work Days! Stay Protected From the Summer Heat

Tel: 1-800-772-6733 Fax: 1-800-772-7702 Web: www.fishersafety.com



Primary

Gatorade Thirst Quencher Drinks::Instant Powder Packets



- 17-816-5** - Pack of 24 and Case of 6 Packs
Drink, Heat Stress, Instant Powder; Gatorade; Carbohydrate-electrolyte fluid-replacement drink scientifically designed for people who engage in strenuous activity; Flavor: Fruit Punch, Size/Yield: 2.12 oz./1 qt. (60mg/1L)
- 17-816-11** - Case of 40
Instant Powder, Fruit Punch, Size/Yield: 8.5 oz./1 gal. (251mL/3.8L)
- 17-816-13** - Case of 32
Instant Powder, Fruit Punch, Size/Yield: 21 oz./2-1/2 gal. (621mL/9.5L)
- 17-816-18** - Case of 14
Instant Powder, Fruit Punch, Size/Yield: 51 oz./6 gal. (1.5L/23L)
- 17-816-8** - Case of 40
Instant Powder, Glacier Freeze, Size/Yield: 8.5 oz./1 gal. (251mL/3.8L)
- 17-816-17** - Case of 14
Instant Powder, Glacier Freeze, Size/Yield: 51 oz./6 gal. (1.5L/23L)
- 17-816-16** - Case of 32
Instant Powder, Glacier Freeze, Size/Yield: 21 oz./2-1/2 gal. (621mL/9.5L)
- 17-816-3** - Pack of 24 and Case of 6 Packs
Instant Powder, Orange, Size/Yield: 2.12 oz./1 qt. (60mg/1L)
- 17-816-9** - Case of 40
Instant Powder, Orange, Size/Yield: 8.5 oz./1 gal. (251mL/3.8L)
- 17-816-14** - Case of 32
Instant Powder, Orange, Size/Yield: 21 oz./2-1/2 g
- Get It**
- 17-816-19** - Case of 14
Instant Powder, Orange, Size/Yield: 51 oz./6 gal. (1.5L/23L)
- 19-034-362G** - Pack of 24 and Case of 6 Packs
Instant Powder, Riptide Rush, Size/Yield: 2.12 oz./1 qt. (60mg/1L)
- 19-086-826** - Case of 40
Instant Powder, Riptide Rush, Size/Yield: 8.5 oz./1 gal. (251mL/3.8L)
- 19-080-490** - Case of 32
Instant Powder, Riptide Rush, Size/Yield: 21 oz./2-1/2 gal. (621mL/9.5L)
- 17-816-4** - Pack of 24 and Case of 6 Packs
Instant Powder, Lemon-Lime, Size/Yield: 2.12 oz./1 qt. (60mg/1L)
- 17-816-10** - Case of 40
Instant Powder, Lemon-Lime, Size/Yield: 8.5 oz./1 gal. (251mL/3.8L)
- 19-086-200** - Case of 14
Instant Powder, Riptide Rush, Size/Yield: 51 oz./6 gal. (1.5L/23L)
- 17-816-15** - Case of 32
Instant Powder, Lemon-Lime, Size/Yield: 21 oz./2-1/2 gal. (621mL/9.5L)
- 17-816-20** - Case of 14
Instant Powder, Lemon-Lime, Size/Yield: 51 oz./6 gal. (1.5L/23L)
- 19-034-363B** - Case of 32
Instant Powder, Variety Pack, Size/Yield: 21 oz./2-1/2 gal. (621mL/9.5L)

Gatorade Coolers



- 17-816-44** - Each
Cooler, Insulated; Rubbermaid; 1 gal. (3.8L) capacity; Easy-to-carry bail handle; Easy-to-clean liner; Orange with white screw-on lid; Gatorade logo on front and back
- 19-037-930** - Each
3-Gallon Cooler
- 19-037-931** - Each
5-Gallon Cooler

Otis Clapp Electrol Tablets



- 18-999-2261** - Each and Case of 6 Each
Tablet, Electrol; Electrolytes; Salt-, sugar- and lactose-free; Dispenser box; 250 packets per dispenser; Two tablets per packet

Ergodyne Chill-Its 6705 Bandana/Headband



19-058-454 - Each and Case of 6 Each

Bandana, Chill-Its 6705; Navy Western; Hook and loop closure; One size; Reusable; Machine washable; Provides cool comfort for 24 to 48 hours when activated in cold water

19-120-2705 - Pack of 6

Black

Ergodyne Hydration Pack



19-150-0067 - Each

Hydration Pack; Ergodyne; Lime; Durable 420D nylon construction; Holds 70 oz. (2L) of water; Closed-cell insulation; Insulated bite valve; Padded, adjustable shoulder and chest straps; Water repellent; abrasion resistant; Machine washable

19-150-0066 - Each

Black

DuPont Cool-Guard Cooling Vest



19-034-984G - Each

Vest, Cooling; Personal; Cool-Guard; Phase-change gel packs; 3-7/8 lbs.; 1-1/2 to 2 hours of cooling at 43.3 deg. C; Recharge in 20 minutes; Blue Banox vest; Light and flexible; Adjustable straps; One-size; Flame-retardant

Ergodyne Chill-Its Phase Vest

NC9259363 - Each

Vest, Phase, Cooling; Chill-its; Small/Medium

NC9259364 - Each

Large/X-Large

North Bulk First Aid Kits



19-130-2483 - Each

Kit, First Aid; Bulk; 10-person size; Waterproof plastic case; ANSI Z308.1-2003 compliant; Ideal for manufacturing settings where a wide variety of first aid items are required

19-130-2485 - Each

25-person size, plastic case

19-130-2487 - Each

50-person size, plastic case

19-130-2489 - Each

75-person size, plastic case

North Construction Unitized First Aid Kit



19-130-2504 - Each

Kit, First Aid; Construction Site; Unitized; Weatherproof metal case; Color-coded supplies; 12-person size; 10L x 3W x 10 in.H

North Insect and Animal Repellant Sprays



19-027-402 - Each and Case of 12 Each
Spray; Wasp, Bee, and Hornet; Range: 10 ft.; Dielectric, safe for electrical machinery; Size: 12 oz.

North Personal Protection Towelettes



19-072-048 - Pack of 50
Towelettes, Insect Repellent; BugX; Effective insect repellent DEET (n,n-diethyl-m-toluamide) in towelettes for easy, on-the-spot application; Each 8 x 5 in. (20.3 x 12.7cm) towelette comes in pocket-sized pouch; Pack of 50 (Dispenser)

19-121-806 - Pack of 100
Insect Repellent Towelette, Pack of 100 (Dispenser)

19-121-805 - Case of 300
Insect Repellent Towelette, Pack of 300 (Bulk)

19-084-723 - Pack of 50
IvyX Precontact Towelettes, Pack of 50 (Dispenser)

19-121-799 - Pack of 100
IvyX Precontact Towelettes, Pack of 100 (Dispenser)

19-084-724 - Case of 300
IvyX Precontact Towelettes, Pack of 300 (Bulk)

19-121-813 - Pack of 50
IvyX Cleanser Towelettes, Pack of 50

19-121-814 - Pack of 100
IvyX Cleanser Towelettes, Pack of 100

19-121-795 - Pack of 50
SunX Sunscreen Towelettes, Pack of 50 (Dispenser)

19-121-797 - Pack of 100
SunX Sunscreen Towelettes, Pack of 100 (Dispenser)

19-121-796 - Case of 300
SunX Sunscreen Towelettes, Pack of 300 (Bulk)

Fisher Racer Series Top Fuel Eyewear



19-042-1006 - Pack of 12 and Case of 10 Packs
Eyewear, Top Fuel; Fisherbrand; Black frames; Clear lens tint; Scratch-resistant polycarbonate lenses; Wraparound design; Lightweight; Meets all ANSI Z87-2003 requirements

AOSafety BX Eyewear



19-130-2635 - Each and Pack of 10 Each
Eyewear, BX, Adjustable soft-tip temples; Universal-fit nose bridge; High-impact polycarbonate lens; Three lens angles; Silver/black frame; Gray; antifog lenses

19-130-2634 - Each and Pack of 10 Each
Clear; antifog lenses

E-A-R Push-Ins Ear Plugs



19-121-095 - Pack of 100 and Case of 4 Packs
Ear Plugs; Push-Ins; NRR: 28dB; Uncorded; Without Grip Rings; EARform soft foam tip; Reusable; 100/Pk

19-121-097 - Pack of 200 and Case of 10 Packs
Uncorded; Without Grip Rings; 200/Pk

19-121-099 - Pack of 500 and Case of 3 Packs
Uncorded; Without Grip Rings; 500/Pk

19-130-1850 - Pack of 200 and Case of 10 Packs
Uncorded; With Grip Rings

Get It

19-121-096 - Pack of 100 and Case of 4 Packs
Corded; Without Grip Rings; 100/Pk

19-121-098 - Pack of 200 and Case of 10 Packs
Corded; Without Grip Rings; 200/Pk

19-121-100 - Pack of 500 and Case of 3 Packs
Corded; With Grip Rings; 500/Pk

19-130-1851 - Pack of 200 and Case of 10 Packs

Corded; With Grip Rings

Get It

Fisherbrand Leather Drivers Gloves



19-013-357 - Pack of 12 and Case of 10 Packs

Gloves, Leather Drivers; Fisherbrand; Intermediate Grade; Ideal for construction, machine operation, utility work, farming, roping, and other general applications; Launderable; Straight Thumb; Elastic Back; Large

Get It

19-013-359 - Dozen and Case of 10

Intermediate Grade; Straight Thumb; Elastic Back; X-Large

Get It

Fisherbrand Standard Leather Palm Gloves



19-013-465 - Dozen and Case of 10

Gloves; Standard Leather Palm; Fisherbrand; Traditional striped fabric back and cuff with split cowhide palm; Gunn Cut; Standard Palm; Small; Safety Cuff; Red cuff

Get It

19-013-466 - Dozen and Case of 10

Gunn Cut; Standard Palm; Large; Safety cuff; Brown Cuff

Get It

Safety Choice Split Cowhide Drivers Gloves



19-042-121 - Dozen and Case of 10

Gloves; Drivers; Split Cowhide Leather; Safety Choice; Abrasion resistant; Excellent dexterity; Straight thumb and elastic back; Regular grade; Large

Get It

19-058-737 - Dozen and Case of 10

Size: X-Large

Get It

Ergodyne GloWEAR Hi-Vis Class II Vests



19-130-2260 - Each and Case of 6 Each

Vest; Ergodyne GloWEAR Hi-Visibility Class II: Economy Mesh Vest with Hook and Loop; Model 8210HL; Orange; Small/Medium; Made of ANSI-certified polyester (5 oz.); 2 in. Scotchlite tape strip; One inside pocket

19-130-2261 - Each and Case of 6 Each

With Hook and Loop; Orange; Large/X-Large

Get It

19-130-2262 - Each and Case of 6 Each

With Hook and Loop; Orange; XX-Large/3X-Large

Get It

19-130-2263 - Each and Case of 6 Each

With Hook and Loop; Orange; 4X-Large/5X-Large

Get It

19-130-2268 - Each

With Zipper closure; Orange; Small/Medium

19-130-2269 - Each

With Zipper closure; Orange; Large/X-Large

19-130-2270 - Each

With Zipper closure; Orange; XX-Large/3X-Large

19-130-2271 - Each

With Zipper closure; Orange; 4X-Large/5X-Large

19-130-2264 - Each and Case of 6 Each

With Hook and Loop; Lime; Small/Medium

19-130-2265 - Each and Case of 6 Each

With Hook and Loop; Lime; Large/X-Large

Get It

19-130-2266 - Each and Case of 6 Each

With Hook and Loop; Lime; 2X-Large/3X-Large

Get It

19-130-2267 - Each

With Hook and Loop; Lime; 4X-Large/5X-Large

Get It

American Innotek Brief Relief Field Lavatory System



19-805-954 - Each

Lavatory, Field; Privacy Tent; Gray; water-resistant; durable; lightweight; Portable; disposal pouches: trash container safe, spill-proof, leak-proof and odorless; 1 Porta Quick PQ310 for Brief Relief

American Innotek Disposa-John Portable Restroom



19-805-951 - Each and Case of 100 Each

Restroom, Portable; Disposa-John; Gas-impervious bag and liner; Polymers and enzymes break down waste into deodorized gel; Virtually odor free; Trash container safe; Includes toilet paper and antiseptic wipe

American Innotek Brief Relief Pouch

19-805-952 - Each and Case of 100 Each

Pouch, Brief Relief; Pocket size; Single use; Sealable bag; Approved for landfill disposal; Unisex; Includes a sanitary wipe